

Finding the new technical page on the web

VWR
Supplier Partnerships for Customer Solutions

Express Order | Promotions | Catalogues | Product Range

Search 23224293 MORE OPTIONS CERTIFICATES OF ANALYSIS MOLECULAR SEARCH

Home | Technical Services | Sitemap | Literature | Careers | About Us | Contact Us

My Profile | Order Tracking | Shopping Basket | Help

Items: 0 Total: £0.00

Refine your search
Search Refinement Keywords:
START SEARCH

Filter by product category
Solvents (1)

Search Results

Your search for 23224293 matched 1 results out of 505,405 documents

Products (1) Content (0)

sorted by: relevancy

	Title	List Price	Info	Article Number	Quantity
	Cyclohexane 1+1	£17.90		23224293	0

go to: 1

SAVE LIST ADD TO BASKET


Home | My Profile | Express Order | Promotions | Product Range
Technical Services | Sitemap | Contact Us | Literature | Careers | About Us

[Terms & Conditions](#) | [Disclaimer & Privacy Policy](#)



Clicking on the "INFO" button gives you this for VWR BDH Prolabo products only

- Last two years batches are selectable
- To get pdf copies just click on the link
- Using "Certificate of analysis" search takes you to the "technical data page" shown here

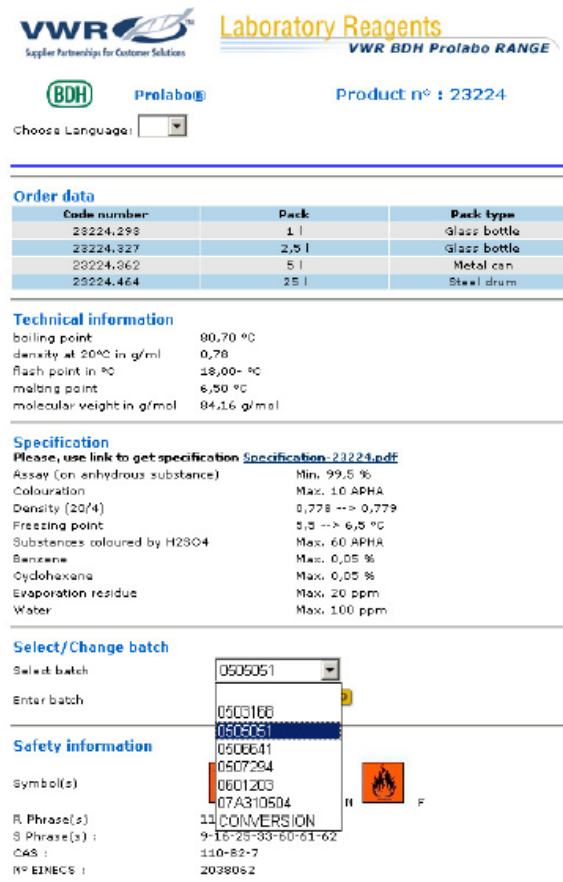

VWR Supplier Partnerships for Customer Solutions
Laboratory Reagents
VWR BDH Prolabo RANGE

BDH **Prolabo** Product n° : 23224
Choose Language:

Order data

Code number	Pack	Pack type
23224.293	1 l	glass bottle
23224.327	2,5 l	glass bottle
23224.362	5 l	Metal can
23224.464	25 l	Steel drum

Technical information

boiling point 80,70 °C
density at 20°C in g/ml 0,78
flash point in °C 18,00- °C
melting point 6,50 °C
molecular weight in g/mol 84,16 g/mol


Specification
Please, use link to get specification [Specification-23224.pdf](#)

Assay (on anhydrous substance) Min. 99,5 %
Colouration Max. 10 APHA
Density (20/4) 0,778 --> 0,779
Freezing point 5,3 --> 6,5 °C
Substances coloured by H2SO4 Max. 60 APHA
Benzene Max. 0,05 %
Cyclohexane Max. 0,05 %
Evaporation residue Max. 20 ppm
Water Max. 100 ppm

Select/Change batch

Switch batch
Enter batch

Safety information

Symbol(s)  F
R Phrase(s)
S Phrase(s) : 9-18-23-33-50-51-62
CAS : 110-82-7
NF/EINECS : 2038062



Searching for Merck products

- Info button will only take you to Merck technical data page or MSDS Sheet
- C of A data only found via "Certificate of Analysis" button, *not via search*
- Need to have batch number- no listing of Merck batches from SAP

